


## VERTICAL IN-LINE FIREPAK | FLOW METER AND JOCKEY PUMP | SUBMITTAL

File No: F43.1057  
Date: DECEMBER 30, 2021  
Supersedes: F43.1057  
Date: APRIL 10, 2019

Job: \_\_\_\_\_ Representative: \_\_\_\_\_  
Order no.: \_\_\_\_\_ Date: \_\_\_\_\_  
Engineer: \_\_\_\_\_ Submitted by: \_\_\_\_\_ Date: \_\_\_\_\_  
Contractor: \_\_\_\_\_ Approved by: \_\_\_\_\_ Date: \_\_\_\_\_

TAG/REF:									
PUMP DATA	FLOW	HEAD	MOTOR DATA	HP	RPM	VOLT	PH	HZ	ENCLOSURE

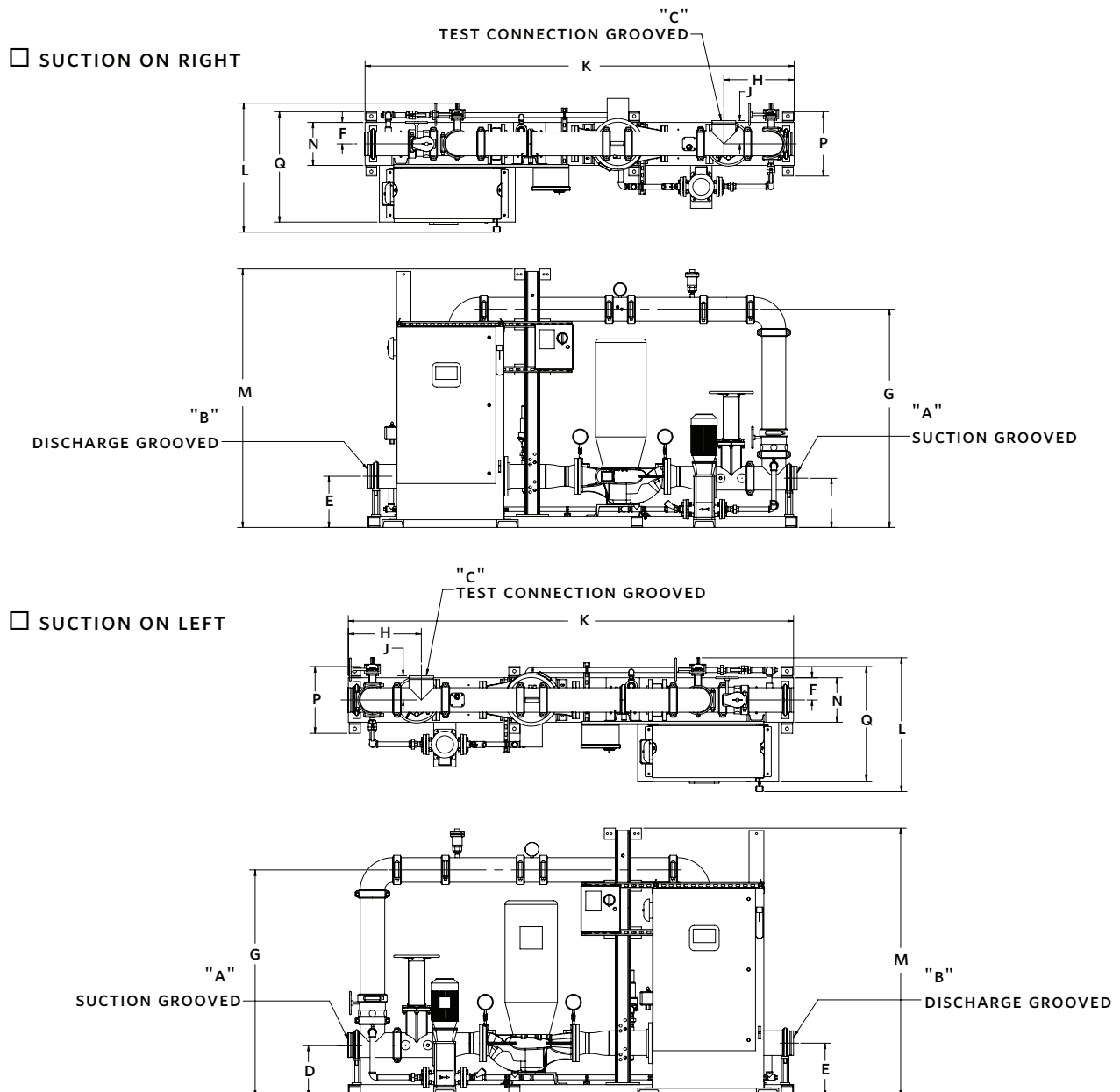

**PUMP DATA**

FLOW (GPM)	PUMP MODEL	DIMENSIONS (INCHES)															MAX SHIPPING WEIGHT* (LBS)
		CONNECTION (GROOVED)									OVERALL DIMENSION (MAX)			BASE DIMENSION			
		A	B	C	D	E	F	G	H	J	K (length)	L (width)	M (height)	N	P	Q (MAX)	
50	2x1.5 LA-F	2.5	2.5	2	10.62	10.62	6.00	52.00	13.12	3.25	120.00	36.00	61.00	12.00	18.00	28.88	1205.00
	2x2x8 FM	2.5	2.5	2	11.47	11.47	6.00	52.00	13.12	3.25	120.00	36.00	61.00	12.00	18.00	30.88	1205.00
75	2x1.5 LA-F	2.5	2.5	2.5	10.37	10.62	6.00	52.00	14.12	3.75	120.00	36.00	61.00	12.00	18.00	28.88	1265.00
	2x2x8 FM	2.5	2.5	2.5	11.22	11.47	6.00	52.00	14.12	3.75	120.00	36.00	61.00	12.00	18.00	30.88	1265.00
100	2x1.5 LA-F	2.5	2.5	2.5	10.37	10.62	6.00	52.00	14.12	3.75	120.00	36.00	61.00	12.00	18.00	28.88	1265.00
	2x2x8 FM	2.5	2.5	2.5	11.22	11.47	6.00	52.00	14.12	3.75	120.00	36.00	61.00	12.00	18.00	30.88	1265.00
150	2x2x8 FM	3	3	3	10.91	11.47	6.00	52.00	15.12	4.25	120.00	36.00	61.00	12.00	18.00	30.88	1305.00
200	3x3x8 FM	3	3	3	12.69	12.69	6.00	52.00	15.12	4.25	120.00	36.00	61.00	12.00	18.00	30.88	1305.00
250	3x3x8 FM	4	4	4	12.19	12.69	6.00	61.00	16.62	5.00	120.00	41.00	72.50	12.00	18.00	30.88	1615.00
300	3x3x8 FM	4	4	4	12.19	12.69	6.00	61.00	16.62	5.00	120.00	41.00	72.50	12.00	18.00	30.88	1650.00
	4x3x9 PF	4	4	4	13.00	13.00	6.00	61.00	16.62	-	120.00	41.00	72.50	12.00	18.00	34.88	1650.00
400	4x3x9 PF	4	4	4	13.00	13.00	6.00	61.00	16.62	-	120.00	41.00	72.50	12.00	18.00	34.88	1650.00
	5x5x8 FM	4	4	4	14.84	14.31	6.00	61.00	16.62	5.00	120.00	41.00	72.50	12.00	18.00	34.88	1695.00
	6x4 LA-F	4	4	4	14.81	13.75	6.00	61.00	16.62	5.00	120.00	41.00	72.50	12.00	18.00	34.88	1640.00
450	4x3x9 PF	6	6	6	11.94	13.00	6.00	61.00	91.72	-	120.00	41.00	72.50	12.00	18.00	34.88	1675.00
	5x5x8 FM	6	6	4	13.78	14.31	6.00	61.00	16.62	5.00	120.00	41.00	72.50	12.00	18.00	30.88	1730.00
	6x4 LA-F	6	6	4	13.75	13.75	6.00	61.00	16.62	5.00	120.00	41.00	72.50	12.00	18.00	34.88	1675.00
500	4x3x9 PF	6	6	6	11.94	13.00	6.00	61.00	91.72	-	120.00	41.00	72.50	12.00	18.00	34.88	1890.00
	5x5x8 FM	6	6	6	13.78	14.31	6.00	61.00	19.68	6.50	120.00	41.00	72.50	12.00	18.00	30.88	1980.00
	6x4 LA-F	6	6	6	13.75	13.75	6.00	61.00	19.68	6.50	120.00	41.00	72.50	12.00	18.00	34.88	1890.00
750	6x4 LB-F	6	6	6	15.13	15.13	6.00	61.00	19.68	6.50	120.00	41.00	72.50	12.00	18.00	34.88	1890.00
	6x5 LY-F	6	6	6	16.63	16.63	6.00	61.00	19.68	6.50	120.00	41.00	72.50	12.00	18.00	30.88	1925.00
1,000	8x8x13 FM	8	8	6	17.19	17.19	7.50	78.00	22.17	6.50	156.00	46.00	84.00	15.00	21.00	37.88	2860.00
	8x8x15 FM	8	8	6	19.59	19.59	7.50	78.00	22.17	6.50	156.00	46.00	84.00	15.00	21.00	37.88	2860.00
	8x8x16 FM	8	8	6	19.59	19.59	7.50	78.00	22.17	6.50	156.00	46.00	84.00	15.00	21.00	37.88	2860.00
1,250	8x8x15 FM	8	8	8	19.59	19.59	7.50	78.00	24.67	7.75	156.00	46.00	84.00	15.00	21.00	37.88	3460.00
	8x8x16 FM	8	8	8	19.59	19.59	7.50	78.00	24.67	7.75	156.00	46.00	84.00	15.00	21.00	37.88	3460.00
1,500	8x8x15 FM	8	8	8	19.59	19.59	7.50	78.00	24.67	7.75	156.00	46.00	84.00	15.00	21.00	37.88	3460.00
	8x8x16 FM	8	8	8	19.59	19.59	7.50	78.00	24.67	7.75	156.00	46.00	84.00	15.00	21.00	37.88	3460.00

TORONTO  
+1 416 755 2291

BUFFALO  
+1 716 693 8813

DROITWICH SPA  
+44 8444 145 145

MANCHESTER  
+44 8444 145 145

BANGALORE  
+91 80 4906 3555

SHANGHAI  
+86 21 5237 0909

SÃO PAULO  
+55 11 4785 1330

LYON  
+33 4 26 83 78 74

DUBAI  
+971 4 887 6775

MANNHEIM  
+49 621 3999 9858

JIMBOLIA  
+40 256 360 030

**NOTE:**

\* Max Shipping Weight does not include Fire Pump, Jockey Pump, or Controller weights